




## Nail Strap

### 2HPS

# Pipe Support

#### Technical Features

- **Sizes:** Fixing hole  $\varnothing$  7mm.
- **Finish :** Electro Zinc Plated
- **Specifications :** Steel Profile: 20x1,0 mm (BxS).  
For Pipe Diameters: 17,2 - 60,3mm.

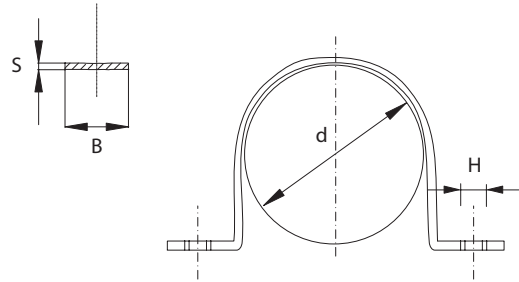

#### Nail Strap - 2HPS

#### Physical Data

Reference	Nominal Pipe Size		d (mm)	H (mm)	Box Qty.	Weight (x1) (kg / lbs)
	metric (DN)	inch				
400678	DN10	3/8"	17,2	7	100	0,01 / 0.02
400679	DN15	1/2"	21,3	7	100	0,01 / 0.02
400680	DN20	3/4"	26,9	7	100	0,02 / 0.04
400681	DN25	1"	33,7	7	100	0,02 / 0.04
400682	DN32	1 1/4"	42,4	7	100	0,03 / 0.07
400683	DN40	1 1/2"	48,3	7	100	0,03 / 0.07
400684	DN50	2"	60,3	7	100	0,03 / 0.07