




## Wall Bracket

### APX (Vertical) & APY (Horizontal)

#### Technical Features

- **Sizes:** to fit with C-Channel
- **Material :** Carbon steel
- **Finish :** Electro-Zinc Plated
- **Specifications :** Both horizontal and vertical supports come complete with fittings, to be used in conjunction with both C-Channels and Strut Channels (See separate datasheets).

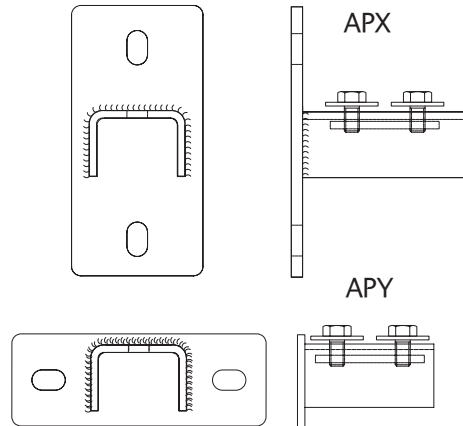

#### Wall Bracket - APX (Vertical) & APY (Horizontal)

#### Physical Data

| Type       | Compatible rail | Rail Section (mm) | Dimensions (mm / inch) |              |              |            | Box Qty.    | Weight (ea.) (kg / lbs) | Reference |
|------------|-----------------|-------------------|------------------------|--------------|--------------|------------|-------------|-------------------------|-----------|
|            |                 |                   | B                      | C            | E            | S          |             |                         |           |
| Vertical   | C-Channel       | 27 x 18 x 1,25    | 31,0 / 1.22            | 50,0 / 1.97  | 114,0 / 4.49 | 5,0 / 0.19 | 10          | 0,40 / 0.88             | 584715    |
|            |                 | 27 x 30 x 1,50    | 31,0 / 1.22            | 50,0 / 1.97  | 114,0 / 4.49 | 5,0 / 0.19 | 10          | 0,40 / 0.88             | 584715    |
|            |                 | 30 x 15 x 2,00    | 31,0 / 1.22            | 50,0 / 1.97  | 114,0 / 4.49 | 5,0 / 0.19 | 10          | 0,40 / 0.88             | 584700    |
|            |                 | 34 x 20 x 1,50    | 36,0 / 1.41            | 50,0 / 1.97  | 114,0 / 4.49 | 5,0 / 0.19 | 10          | 0,42 / 0.92             | 584710    |
|            |                 | 34 x 20 x 2,4     | 36,0 / 1.41            | 50,0 / 1.97  | 114,0 / 4.49 | 5,0 / 0.19 | 10          | 0,42 / 0.92             | 584710    |
|            |                 | 35 x 35 x 2,00    | 43,0 / 1.69            | 70,0 / 2.75  | 144,0 / 5.67 | 5,0 / 0.19 | 10          | 0,82 / 1.80             | 584725    |
|            | 38 x 40 x 2,00  | 43,0 / 1.69       | 70,0 / 2.75            | 144,0 / 5.67 | 5,0 / 0.19   | 10         | 0,82 / 1.80 | 584725                  |           |
|            | Strut-Channel   | All               | 43,0 / 1.69            | 70,0 / 2.75  | 144,0 / 5.67 | 5,0 / 0.19 | 10          | 0,82 / 1.80             | 584725    |
| Horizontal | C-Channel       | 27 x 18 x 1,25    | 31,0 / 1.22            | 40,0 / 1.57  | 124,0 / 4.88 | 5,0 / 0.19 | 10          | 0,30 / 0.66             | 584758    |
|            |                 | 27 x 30 x 1,50    | 31,0 / 1.22            | 40,0 / 1.57  | 124,0 / 4.88 | 5,0 / 0.19 | 10          | 0,30 / 0.66             | 584758    |
|            |                 | 30 x 15 x 2,00    | 31,0 / 1.22            | 40,0 / 1.57  | 124,0 / 4.88 | 5,0 / 0.19 | 10          | 0,30 / 0.66             | 584758    |
|            |                 | 34 x 20 x 1,50    | 36,0 / 1.41            | 40,0 / 1.57  | 124,0 / 4.88 | 5,0 / 0.19 | 10          | 0,32 / 0.70             | 584740    |
|            |                 | 34 x 20 x 2,4     | 36,0 / 1.41            | 40,0 / 1.57  | 124,0 / 4.88 | 5,0 / 0.19 | 10          | 0,32 / 0.70             | 584740    |
|            |                 | 35 x 35 x 2,00    | 43,0 / 1.69            | 50,0 / 1.97  | 144,0 / 5.67 | 5,0 / 0.19 | 10          | 0,80 / 1.76             | 584751    |
|            | 38 x 40 x 2,00  | 43,0 / 1.69       | 50,0 / 1.97            | 144,0 / 5.67 | 5,0 / 0.19   | 10         | 0,80 / 1.76 | 584751                  |           |
|            | Strut-Channel   | All               | 43,0 / 1.69            | 50,0 / 1.97  | 144,0 / 5.67 | 5,0 / 0.19 | 10          | 0,80 / 1.76             | 584751    |

