




## Pipe Clamp without Insulation

### HDPC

#### Technical Features

- **Sizes (Pipe Accomodation Diameter):** 22mm through 146mm
- **Hanger Thread Size :** For diameters from 22mm to 65mm M8/M10 Combination Boss. For diameters from 76mm to 116mm M10/M12 Combination Boss. For diameters from 140mm to 146mm M12/M16 Combination Boss. For
- **Closure Cylinder Head Screw Sizes :** M6x20 to M8x25
- **Materials :**  
Profile: Carbon steel
- **Finish :** Electro Zinc Plated
- **Approvals :** 3/4" - 10" VdS and 3/4" - 4" FM

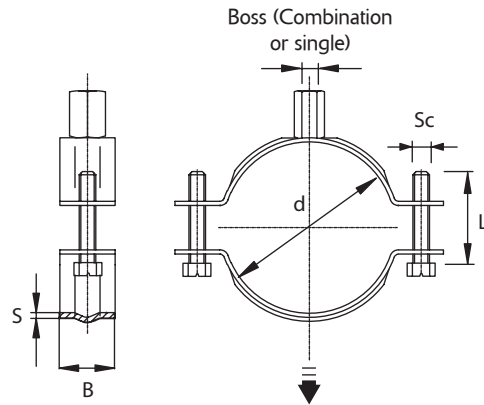

### Pipe Clamp without Insulation - HDPC

#### Physical Data

| Reference | Approvals | Nominal Pipe Size |        | Boss Thread | B x S (mm) | Sc x L | d (mm)  | Box Qty. | Weight (x1) (kg / lbs) |
|-----------|-----------|-------------------|--------|-------------|------------|--------|---------|----------|------------------------|
|           |           | metric (DN)       | inch   |             |            |        |         |          |                        |
| 598170    | VdS / FM  | DN20              | 3/4"   | M8/M10      | 20x1,5     | M6x20  | 22-30   | 50       | 0,05 / 0.12            |
| 598171    | VdS / FM  | DN25              | 1/2"   | M8/M10      | 20x1,5     | M6x20  | 31-35   | 50       | 0,05 / 0.12            |
| 598172    | VdS / FM  | DN32              | 1 1/4" | M8/M10      | 20x1,5     | M6x20  | 40-45   | 50       | 0,05 / 0.12            |
| 598173    | VdS / FM  | DN40              | 1 1/2" | M8/M10      | 20x1,5     | M6x20  | 48-53   | 50       | 0,07 / 0.15            |
| 598174    | VdS / FM  | DN50              | 2"     | M8/M10      | 20x2,0     | M6x20  | 60-65   | 50       | 0,08 / 0.18            |
| 598175    | VdS / FM  | DN65              | 2 1/2" | M10/M12     | 20x2,0     | M6x25  | 76-81   | 25       | 0,08 / 0.18            |
| 598176    | VdS / FM  | DN80              | 3"     | M10/M12     | 20x2,0     | M6x25  | 88-94   | 25       | 0,09 / 0.20            |
| 598177    | VdS / FM  | DN100             | 4"     | M10/M12     | 20x2,0     | M6x25  | 110-116 | 25       | 0,09 / 0.20            |
| 598178    | VdS       | DN125             | 5"     | M12/M116    | 20x2,0     | M6x25  | 140-146 | 10       | 0,13 / 0.29            |
| 598179    | VdS       | DN150             | 6"     | M12/M116    | 20x2,0     | M6x25  | 140-146 | 10       | 0,17 / 0.38            |
| 598180    | VdS       | DN200             | 8"     | M16         | 20x2,0     | M6x25  | -       | 1        | 0,17 / 0.38            |
| 598181    | VdS       | DN250             | 10"    | M20         | 23x2,5     | M6x25  | -       | 1        | 0,17 / 0.38            |