




Slide (Heavy and Medium Duty)


PCG

Technical Features

- **Sizes** : Medium M10
Heavy M12/M16
- **Temperature Rating** : from -40°C up to +100°C
- **Finish** : Electro Zinc Plated

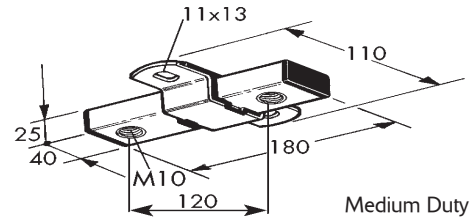

Medium Duty

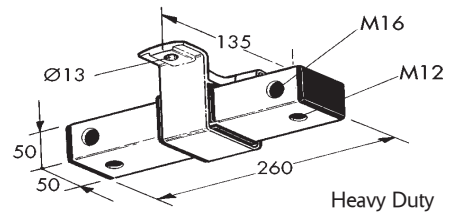

Heavy Duty

Pipe Support

Slide - PCG

Physical Data

Reference	Thread	Maximum Distance	Ø hole	Max. Load	Box Qty.	Weight (x1) (kg / lbs)
588170	M10	55mm	M6x25	1.5 kN	1	0,50 / 1.10
588180	M12/M16	125mm	M6x25	7.8 kN	1	2,26 / 4.99