


Saddle-Let Small Mechanical Tee

Class 723 Threaded Outlet

Technical Features

- Available sizes (Pipe Size) : DN50/2" through DN200/8".
- Max Working Pressure : 12 bar (175 psi)
- Material : Ductile Iron to ASTM A536, Gr. 65-45-12.
- Finish : Painted Red, Galvanised or Epoxy Coated.
- Connections : Female threaded only, with ISO pipe outlets.

Bolt Fastening Torque
40N~m (29Lb-Ft)

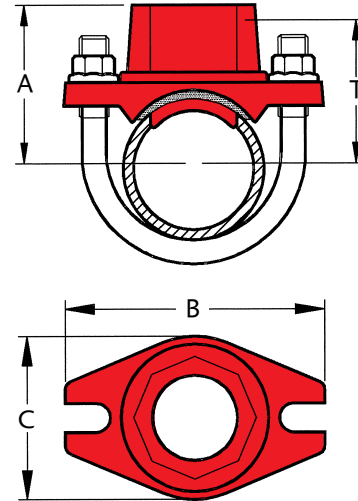

Class 723
Saddle-Let Small Mechanical Tee

Grooved Products

Saddle-Let Small Mechanical Tee - Class 723 Threaded Outlet

Physical Data

Pipe O.D.		Hole Dia. +1.6, -0/+0.063, -0 mm/inch	Dimensions (mm/inch)			Take-Out T*	Weight Kgs/lbs	Reference		
mm	inch		A	B	C			Painted	Galvanized	Black
42.2 x DN15	1.25 x 0.5	30 / 1.18	53.0 / 2.08	89.0 / 3.50	56.0 / 2.20	35.0 / 1.38	0.4 / 0.9	723/042021	723/042021G	723/042021BK
42.2 x DN20	1.25 x 0.75	30 / 1.18	53.0 / 2.08	89.0 / 3.50	56.0 / 2.20	35.0 / 1.38	0.4 / 0.9	723/042027	723/042027G	723/042027BK
42.2 X DN25	1.25 x 1	30 / 1.18	56.0 / 2.20	89.0 / 3.50	56.0 / 2.20	38.0 / 1.50	0.4 / 0.9	723/042034	723/042034G	723/042034BK
48.3 X DN15	1.5 x 0.5	30 / 1.18	55.0 / 2.16	89.0 / 3.50	56.0 / 2.20	35.0 / 1.38	0.4 / 0.9	723/048021	723/048021G	723/048021BK
48.3 X DN20	1.5 x 0.75	30 / 1.18	55.0 / 2.16	89.0 / 3.50	56.0 / 2.20	35.0 / 1.38	0.4 / 0.9	723/048027	723/048027G	723/048027BK
48.3 X DN25	1.5 x 1	30 / 1.18	58.0 / 2.28	89.0 / 3.50	56.0 / 2.20	35.0 / 1.38	0.4 / 0.9	723/048034	723/048034G	723/048034BK
60.3 X DN15	2 x 0.5	30 / 1.18	64.0 / 2.51	98.0 / 3.85	56.0 / 2.20	42.0 / 1.65	0.4 / 0.9	723/060021	723/060021G	723/060021BK
60.3 X DN20	2 x 0.75	30 / 1.18	64.0 / 2.51	98.0 / 3.85	56.0 / 2.20	42.0 / 1.65	0.4 / 0.9	723/060027	723/060027G	723/060027BK
60.3 X DN25	2 x 1	30 / 1.18	67.0 / 2.63	98.0 / 3.85	56.0 / 2.20	45.0 / 1.77	0.4 / 0.9	723/060034	723/060034G	723/060034BK
76.1 X DN15	2.5 x 0.5	30 / 1.18	69.0 / 2.71	111.0 / 4.37	56.0 / 2.20	51.0 / 2.00	0.4 / 0.9	723/076021	723/076021G	723/076021BK
76.1 X DN20	2.5 x 0.75	30 / 1.18	69.0 / 2.71	111.0 / 4.37	56.0 / 2.20	51.0 / 2.00	0.4 / 0.9	723/076027	723/076027G	723/076027BK
76.1 X DN25	2.5 x 1	30 / 1.18	72.0 / 2.83	111.0 / 4.37	56.0 / 2.20	54.0 / 2.13	0.4 / 0.9	723/076034	723/076034G	723/076034BK

* T: Centre of pipe run to end of outlet pipe (approximate dimensions). Female threaded only.