


Multi-Jet Controller

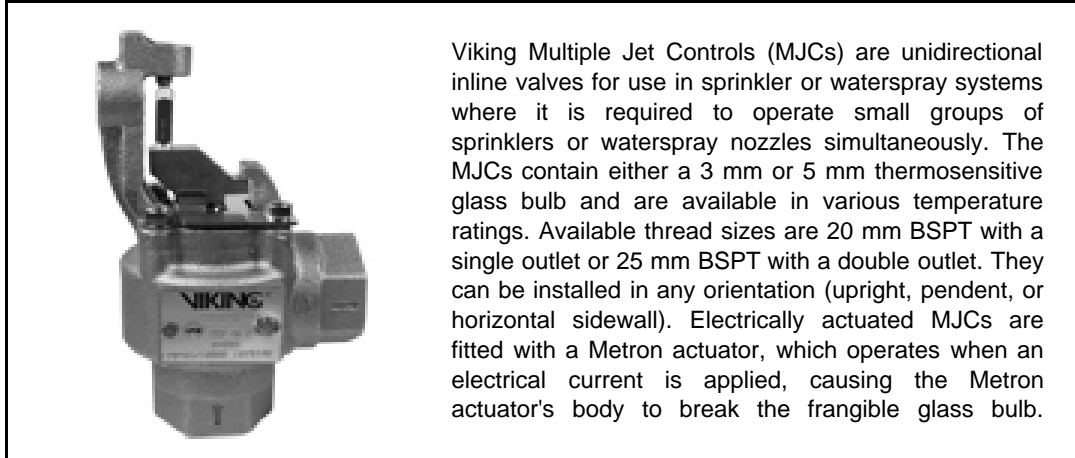

Viking Multiple Jet Controls (MJs) are unidirectional inline valves for use in sprinkler or waterspray systems where it is required to operate small groups of sprinklers or waterspray nozzles simultaneously. The MJs contain either a 3 mm or 5 mm thermosensitive glass bulb and are available in various temperature ratings. Available thread sizes are 20 mm BSPT with a single outlet or 25 mm BSPT with a double outlet. They can be installed in any orientation (upright, pendent, or horizontal sidewall). Electrically actuated MJs are fitted with a Metron actuator, which operates when an electrical current is applied, causing the Metron actuator's body to break the frangible glass bulb.

Thread Size	Bulb ¹	Outlet	Part Number	Finish ²	Temp Rating	IPG	List Price
20 mm BSPT	3 mm	Single	16753AB	Brass	155°F / 68°C	V25.3D	\$425.00
20 mm BSPT	3 mm	Single	16753AD	Brass	175°F / 79°C	V25.3D	\$425.00
20 mm BSPT	3 mm	Single	16753AE	Brass	200°F / 93°C	V25.3D	\$425.00
20 mm BSPT	3 mm	Single	16753AG	Brass	286°F / 141°C	V25.3D	\$425.00
20 mm BSPT	5 mm	Single	16751AB	Brass	155°F / 68°C	V25.3D	\$425.00
20 mm BSPT	5 mm	Single	16751AD	Brass	175°F / 79°C	V25.3D	\$425.00
20 mm BSPT	5 mm	Single	16751AE	Brass	200°F / 93°C	V25.3D	\$425.00
20 mm BSPT	5 mm	Single	16751AG	Brass	286°F / 141°C	V25.3D	\$425.00
20 mm BSPT	5 mm	Single	16751AH	Brass	360°F / 182°C	V25.3D	\$425.00
20 mm BSPT	5 mm	Single	16751AL	Brass	500°F / 260°C	V25.3D	\$425.00
25 mm BSPT	3 mm	Double	16992AB	Brass	155°F / 68°C	V25.3D	\$425.00
25 mm BSPT	3 mm	Double	16992AD	Brass	175°F / 79°C	V25.3D	\$425.00
25 mm BSPT	3 mm	Double	16992AE	Brass	200°F / 93°C	V25.3D	\$425.00
25 mm BSPT	3 mm	Double	16992AG	Brass	286°F / 141°C	V25.3D	\$425.00
25 mm BSPT	5 mm	Double	16991AB	Brass	155°F / 68°C	V25.3D	\$425.00
25 mm BSPT	5 mm	Double	16991AD	Brass	175°F / 79°C	V25.3D	\$425.00
25 mm BSPT	5 mm	Double	16991AE	Brass	200°F / 93°C	V25.3D	\$425.00
25 mm BSPT	5 mm	Double	16991AG	Brass	286°F / 141°C	V25.3D	\$425.00
25 mm BSPT	5 mm	Double	16991AH	Brass	360°F / 182°C	V25.3D	\$425.00
25 mm BSPT	5 mm	Double	16991AL	Brass	500°F / 260°C	V25.3D	\$425.00

(1) Viking's MJC valves can also be ordered with an optional Metron device for electrical actuation of the valve.

Please contact Viking customer service for pricing and availability.

(2) MJC valves are not suitable for corrosive environments or use with sea water