




# REPLACEMENT PARTS

## DELUGE VALVE MODEL D-5

3" (DN80), 4" (DN100), 6" (DN150)

Manufactured  
3" 1974 - 1985  
4" 1973 - 1985  
6" 1972 - 1984

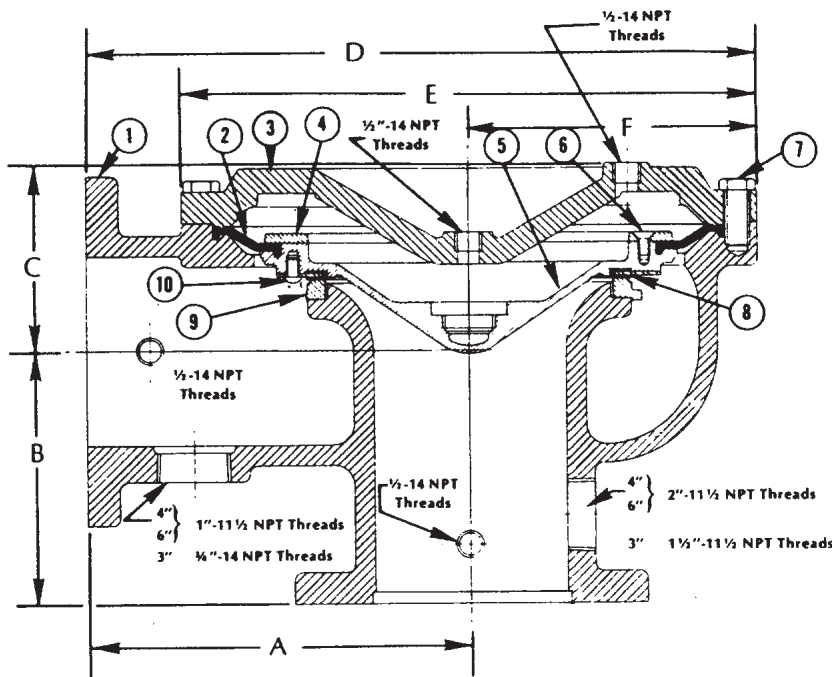

**NOTE:** Model D-5 Clapper Assembly is interchangeable with Model D-4 clapper. The rubbers are bonded to the clapper on Model D-4. Use Model D-5 Clapper Assembly for replacement.

Valve Size	A	B	C	D	E	F
3" (DN75)	7" (177,8 mm)	5" (127 mm)	3-3/4" (96,8 mm)	12-3/8" (314,3 mm)	10-3/4" (273 mm)	5-3/8" (136,5 mm)
4" (DN100)	8-1/2" (215,9 mm)	6-1/2" (165 mm)	4-3/4" (120,6 mm)	15-1/2" (393,7 mm)	14" (335,6 mm)	7" (177,8 mm)
6" (DN150)	12" (304,8 mm)	8" (203 mm)	5-7/8" (149,2 mm)	21-1/8" (536,5 mm)	8-1/4" (209,5 mm)	9-1/8" (231,7 mm)

ITEM NO.	PART NUMBER			DESCRIPTION	MATERIAL	NO. REQ'D		
	3" (DN80)	4" (DN100)	6" (DN150)			3" (DN80)	4" (DN100)	6" (DN150)
1	--	--	--	Body	Cast Iron	1	1	1
2	02492C	02377B	01974C	Diaphragm Rubber	EPDM	1	1	1
3	--	--	--	Cover	Cast Iron	1	1	1
4	02493B	02378B	05704B	Clamp Ring	Bronze UNS-C84400	1	1	1
5	08846N	08844N	08570N	Clapper	Ductile Iron 65-45-12 Teflon Coated	1	1	1
6	02494A			Screw, R.H.P. 10-24 X 1/2"	Stainless Steel UNS-S30400	6		
		02383A		Screw, H.H.C. 5/16-18 X 1/2"	Stainless Steel UNS-S30400		8	
			01977A	Screw, F.H.S. 3/8-16 X 3/4"	Stainless Steel UNS-S30400			12
7	01923A			Screw, H.H.C. 3/4-10 X 1-1/2"	Steel	8		
		13576	13576	Screw, H.H.C. 3/4-10 X 1-3/4"	Steel		10	15
8	02497B	02382B	02176B	Seat Rubber	EPDM / Stainless Steel	1	1	1
9	--	--	--	Seat	Bronze	1	1	1
10	02496A			Screw, H.H.C. 10-24 X 3/8"	Stainless Steel UNS-S30400	6		
		02383A		Screw, H.H.C. 5/16-18 X 1/2"	Stainless Steel UNS-S30400		8	
			07932	Screw, H.H.C. 3/8-16 X 1/2"	Stainless Steel UNS-S30400			12

--Indicates no replacement part available

### SUB-ASSEMBLY

2, 4-6, 8, 10	02491B	02376B	R8402315B	Clapper Assembly
---------------	--------	--------	-----------	------------------