

Fig. 64 - Steel “C” Clamp with Locknut

Size Range — 3/8" thru 7/8" rod

Material — Carbon Steel


Function — For attachment to I-beams, channels, and wide flange beams where the thickness does not exceed 3/4".
Hardened set screw secures “C” Clamp to beam.

Approvals — Conforms to Federal Specification WW-H-171E, Type 23 and Manufacturers Standardization Society SP-69, Type 23.

Finish — Plain

Note — Available in Electro-Galvanized and HDG finish or Stainless Steel materials.

Order By — Figure number, rod size and finish

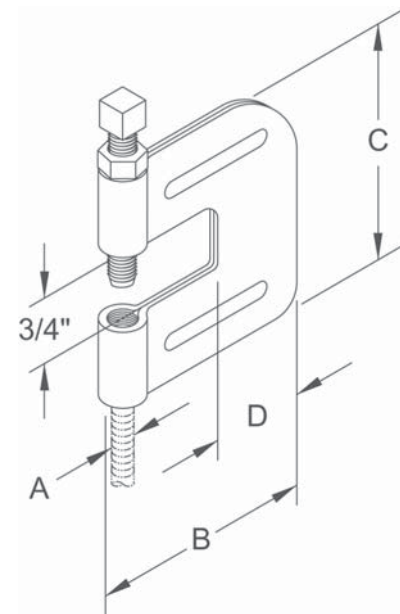

Dimensions • Weights

Max. Pipe Size	Rod Size A	B	C	D	Max. Rec. Load Lbs.	Approx. Wt./100
2	3/8	2 3/8	2 3/8	1	400	40
3 1/2	1/2	2 3/8	2 3/8	1	400	50
5	5/8	2 3/8	2 3/8	1	550	70
6	3/4	2 5/16	2 3/8	1	630	83
*8	7/8	3 5/16	3	1 3/8	1200	158

* Throat opening is 1".

