




REPLACEMENT PARTS

EASY RISER® SWING
CHECK VALVE OBSOLETE
MODELS E-1

Manufactured 1989 - 1995

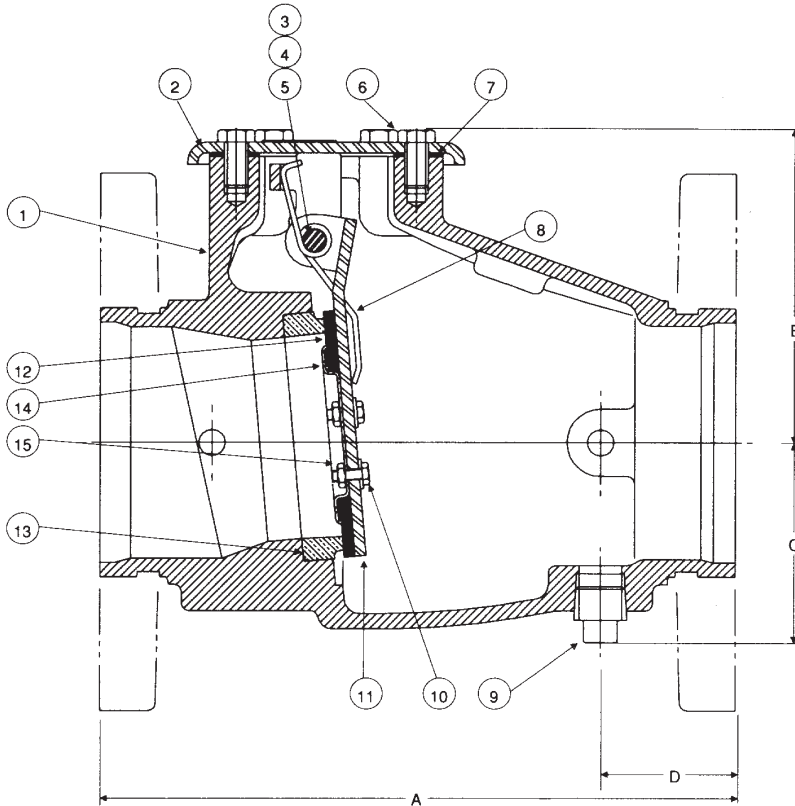

Size	A	B	C	D
2-1/2" (DN65)	9" (229 mm)	4-1/2" (114 mm)	2-5/8" (67 mm)	2" (51 mm)
3" (DN80)	9-1/2" (241 mm)	4-3/4" (121 mm)	2-3/4" (70 mm)	2" (51 mm)
4" (DN100)	10-5/8" (270 mm)	5-3/16" (132 mm)	3-3/8" (86mm)	2-1/8" (54 mm)
6" (DN150)	13-5/8" (346 mm)	6-3/4" (172 mm)	4-3/8" (111 mm)	2-1/4" (57 mm)

ITEM NO.	PART NUMBER			DESCRIPTION	MATERIAL	NO. REQ'D		
	3" (DN80)	4" (DN100)	6" (DN150)			3"	4"	6"
1	--	--	--	Body	Ductile Iron	1	1	1
2	--	--	--	Cover Assembly	HSLA Stainless Steel	1	1	1
3	05355A	04900A	04991A	Hinge Pin	Stainless Steel	1	1	1
4	05445A	05445A	05445A	Retaining Ring	Stainless Steel	2	2	2
5	--	--	--	Pin Washer	Stainless Steel	0	2	2
6	01517A	01517A	04991A	3/8-16 x 3/4 Lg. H.H.C. Screw	Zinc Plated Steel	4	6	0
			04993A	1/2-13 x 7/8 Lg. H.H.C. Screw	Zinc Plated Steel	0	0	6
7	05354B	04649B	04992B	Cover Gasket	SBR Rubber	1	1	1
8	06021B	05939B	05940B	Torsion Spring	Stainless Steel	1	1	1
9	01925S	01925S	01925S	Pipe Plug, 1/2"	Cast Iron	1	1	1
10	*	*		Sealing Washer	EPDM & Stainless Steel	1	1	
			*	Sealing Washer	EPDM & Stainless Steel			1
	*	*		Screw, Button Head, Socket, 3/8"-24 UNF x 1/2" (12,7 mm) lg.	Stainless Steel, UNS-S30400	1	1	
			*	Screw, Button Head, Socket, 1/4"-20 UNF x 3/4" (19,0 mm) lg.	Stainless Steel, UNS-S30400			1
11	*	*	*	Clapper	HRS	1	1	1
				Clapper	Stainless Steel	0	0	0
12	*	*	*	Clapper Rubber	E.P.D.M.	1	1	1
13	--	--	--	Seat	Brass	1	1	1
14	*	*	*	Rubber Retainer	Stainless Steel	1	1	1
15	*	*		Clapper Hex Nut 3/8"-24 UNC	Stainless Steel	1	1	
			*	Clapper Hex Nut 1/2"-13 UNC	Stainless Steel			1

-- Indicates replacement part not available

* Indicates replacement part only available in a Sub-Assembly, as indicated below.

SUB-ASSEMBLY

10-12 14, 15	08518	08519	08520	Clapper Assembly
--------------	-------	-------	-------	------------------

Note: Clapper is single bolt style with Ryton bushings for hinge pin.
A bushing is included but not used.