




# REPLACEMENT PARTS

# FLOW CONTROL VALVE MODEL G-2

2", 3", 4" & 6" (DN 50, DN80, DN100 & DN150)

Manufactured 1979 - 1985

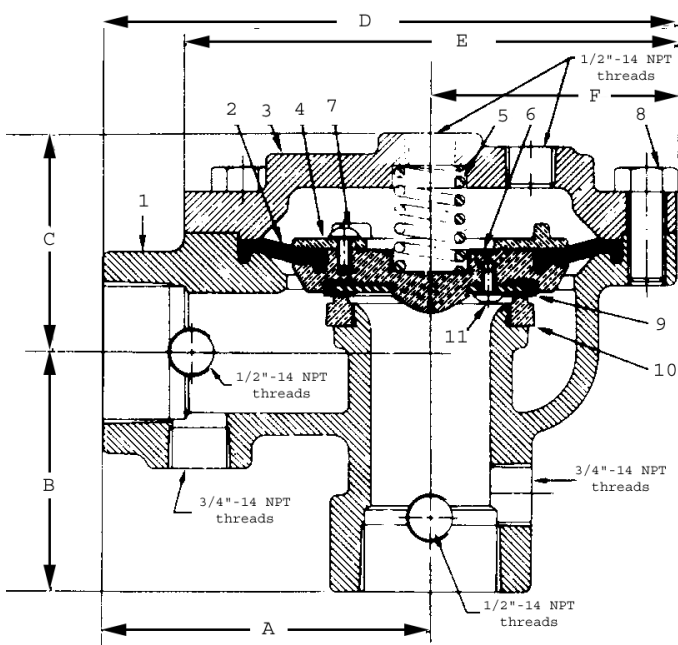

	Valve Size			
	2" (DN50)	3" (DN80)	4" (DN100)	6" (DN150)
<b>A</b>	5-1/2" (140mm)	7" (178mm)	8-1/2" (216mm)	12" (305mm)
<b>B</b>	4" (101.6mm)	5" (127mm)	6-1/2" (165mm)	8" (203mm)
<b>C</b>	3-5/8" (92mm)	3-13/16" (97mm)	4-3/4" (120.6mm)	7-11/16" (195mm)
<b>D</b>	9-5/8" (243.4mm)	12-3/8" (314.3mm)	15-1/2" (394mm)	21-1/8" (536.5mm)
<b>E</b>	8-1/4" (209.5mm)	10-3/4" (273mm)	14" (335.6mm)	8-1/4" (209.5mm)
<b>F</b>	4-1/8" (105mm)	5-3/8" (136.5mm)	7" (178mm)	9-1/8" (232mm)

ITEM NO.	PART NUMBER				DESCRIPTION	MATERIAL	NO. REQ'D.			
	2"	3"	4"	6"			2"	3"	4"	6"
1	--	--	--	--	Body	Cast Iron	1	1	1	1
2	04223B	02492C	02377B	01974C	Clapper Rubber	EPDM	1	1	1	1
3	--	--	--	--	Cover	Cast Iron	1	1	1	1
4	04224B	02493B	02378B	05704B	Clamp Ring	Brass	1	1	1	1
5	01905A	01910A	01915A	--	Spring	Stainless Steel	1	1	1	1
6	*	*	*	*	Clapper	Brass	1	1	1	1
7	02494A	02494A			Screw, R.H., 10-24 x 1/2" Lg.	Stainless Steel	4	6		
			02383A		Screw, H.H.C, 5/16-18 x 1/2" Lg.	Stainless Steel			8	
				02454A	Screw, H.H.C, 3/8-16 x 5/8" Lg.	Stainless Steel				12
8	01922A				Screw, H.H.C, 5/8-11 x 1-1/4" Lg.	Steel	6			
		01923A			Screw, H.H.C, 3/4-10 x 1-1/2" Lg.	Steel		8		
			13576	13576	Screw, H.H.C, 3/4-10 x 1-3/4" Lg.	Steel			10	15
9	04225B	02497B	02382B	02176B	Seat Rubber	EPDM/Stainless Steel	1	1	1	1
10	--	--	--	--	Seat	Cast Bronze	1	1	1	1
11	02494A				Screw, R.H., 10-24 x 1/2" Lg.	Stainless Steel	4			
		02496A			Screw, R.H., 10-24 x 3/8" Lg.	Stainless Steel		6		
			02383A		Screw, H.H.C, 5/16-18 x 1/2" Lg.	Stainless Steel			8	
				07932	Screw, H.H.C, 3/8-16 x 1/2" Lg.	Stainless Steel				12

--Indicates no replacement part available

\*Indicates replacement part is only available in Sub-Assembly listed below

**Sub-Assembly**

2, 4, 6, 7, 9, 11	04221B	02491B	02376B	05703B	Clapper Assembly
-------------------	--------	--------	--------	--------	------------------