



TECHNICAL DATA

ELECTRIC RELEASE MODULE TRIM CHART


Maximum 250 psi Water Working Pressure

The Viking Corporation, 210 N Industrial Park Drive, Hastings MI 49058

Telephone: 269-945-9501 | Technical Services: 877-384-5464 | Fax: 269-818-1680 | Email: techsvcs@vikingcorp.com

Visit the Viking website for the latest edition of this technical data page www.vikinggroupinc.com

Available since 1999.

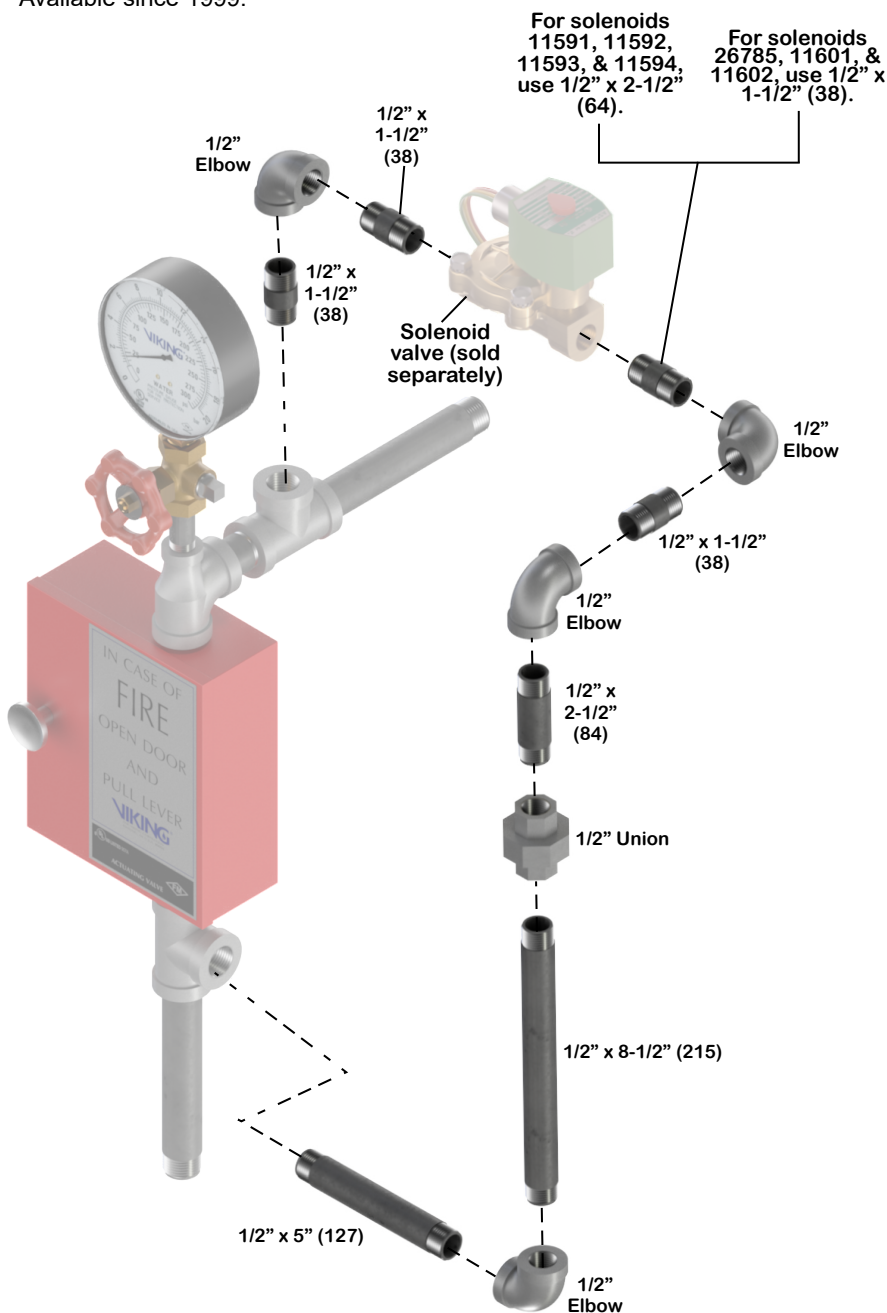

For Use on Standard Trim	For Use on Galvanized Trim	For Use on Brass* Trim	For Use on Stainless Steel* Trim
10830	10830USA	10832	10831
<p>NOTE: Order solenoid valve separately. Electric Release Module is used with the Viking solenoid valve part nos. 26785 (monitored), 11591, 11592, 11593, 11594, 11601, and 11602.</p> <p>The Viking Electric Release Module is only for Viking deluge and flow control valves. Verify that the control valves use conventional trim and that the trim is installed in accordance with the valve's current conventional trim chart. Install the Electric Release Module by using the provided connections and Figure 1 (left).</p> <p>*Where brass and stainless steel trim are recommended, refer to Viking Corp's website for a description on the Halar®-coated deluge valve and associated trim diagrams.</p>			

WARNING: Cancer and Reproductive Harm-
www.P65Warnings.ca.gov

**ORDER DELUGE VALVE,
TRIM, SOLENOID VALVE,
AND RELEASE MODULE
TRIM SEPARATELY.**

FIGURE 1: ELECTRIC RELEASE MODULE