




Pipe Clamp with Rubber Insulation

280

Technical Features

- **Sizes (Pipe Accomodation Diameter):** 57mm through 326mm
- **Hanger Thread Size :** M8/M12 Combination Boss.
- **Closure Cylinder Head Screw Sizes :** M8x25 to M12x35
- **Temperature Rating :** from -50°C up to +110°C
- **Fire Rating :** B2 acc. to DIN 4102
- **Materials :**
 Profile: Carbon steel
 Rubber: EPDM
- **Finish :** Electro Zinc Plated
- **Specification :** To be used with Threaded Rod (not supplied).
 EPDM rubber insulated for sound reduction, compliant with DIN 4109

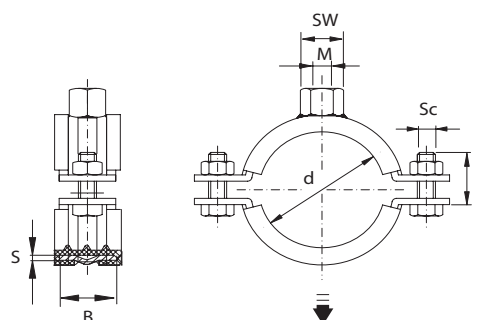

Pipe Clamp with Rubber Insulation - 280

Physical Data

Reference	Nominal Pipe Size		SW-M	Thread	B x S (mm)	Sc x L	d (mm)	Box Qty.	Weight (x1) (kg / lbs)
	metric (DN)	inch							
400929	DN50	2"	SW17-M10	M10	30x3,0	M8x25	57-61	25	0,08 / 0.18
400930	63-67mm	-	SW17-M10	M10	30x3,0	M8x25	63-67	25	0,28 / 0.62
400931	70-73mm	-	SW19-M12	M12	30x3,0	M8x25	70-73	25	0,32 / 0.71
400932	DN65	2 1/2"	SW19-M12	M12	30x3,0	M8x25	74-78	25	0,37 / 0.82
400933	DN80	3"	SW19-M12	M12	30x3,0	M8x25	83-91	25	0,40 / 0.88
400934	101-106mm	-	SW19-M12	M12	30x3,0	M8x25	101-106	25	0,44 / 0.97
400935	DN100	4"	SW19-M12	M12	30x3,0	M8x25	108-114	25	0,47 / 1.04
400936	115-116mm	-	SW19-M12	M12	30x3,0	M8x25	115-116	10	0,20 / 0.44
400937	125mm	-	SW19-M12	M12	30x3,0	M8x25	125	10	0,21 / 0.46
400938	131-135mm	-	SW19-M12	M12	30x3,0	M8x25	131-135	10	0,55 / 1.21
400939	DN125	5"	SW19-M12	M12	30x3,0	M8x25	136-139	10	0,57 / 1.26
400940	140-144mm	-	SW19-M12	M12	30x3,0	M8x25	140-144	10	0,58 / 1.28
400941	159-163mm	-	SW24-M16	M12	38x4,0	M10x35	159-163	10	1,03 / 2.27
400942	DN150	6"	SW24-M16	M12	38x4,0	M10x35	165-169	10	1,11 / 2.45
400943	193-200mm	-	SW24-M16	M12	38x4,0	M10x35	193-200	10	1,21 / 2.67
400944	210-212mm	-	SW24-M16	M12	40x4,0	M12x35	210-212	10	1,39 / 3.07
401248	DN200	8"	SW24-M16	M12	40x4,0	M12x35	216-220	10	1,44 / 3.18
401249	245-252mm	-	SW24-M16	M12	40x4,0	M12x35	245-252	10	1,62 / 3.58
401250	DN250	10"	SW24-M16	M12	40x4,0	M12x35	267-275	10	1,71 / 3.77
401251	298-305mm	-	SW24-M16	M12	40x4,0	M12x35	298-305	10	1,88 / 4.15
401252	DN300	12"	SW24-M16	M16	40x4,0	M12x35	323-326	10	2,02 / 4.46