

VIKING DRY SPRINKLER ORDER FORM

Customer: _____


Date: _____

PO#/Job: _____

Ship to: _____

Dry sprinklers are custom made and NOT RETURNABLE.
Please follow these steps to ensure an accurate order

1. Check the desired SIN (Sprinkler Identification Number).
2. Check desired sprinkler finish and temperature.
 (Circle temp and finish for fusible link models.)
3. Enter A or B dimensions - see page 2 for dimensional references.
4. Enter order quantity.

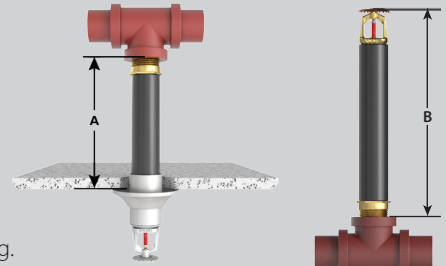

A Dimension is the distance from the face of the fitting (tee) to desired finished surface of ceiling.

B Dimension is the distance from the face of the fitting (tee) to the top of the deflector - upright models only.

Standard Adjustable	Pendent <input type="checkbox"/> VK154 (SR) <input type="checkbox"/> VK163 (SR LO) <input type="checkbox"/> VK176 (QR) <input type="checkbox"/> VK177 (QR LO) <input type="checkbox"/> VK286 (QR LO*) *Fusible Link 165° 205° 280° (Circle temp)	ELO Pendent <input type="checkbox"/> VK546 (SR ELO)* <input type="checkbox"/> VK549 (QR ELO)* *Fusible Link 165° 205° 280° Brass Chrome White (Circle temp and finish) Lengths in 6" increments, 12"-28" Note: Insulating boot included.	Horizontal Sidewall <input type="checkbox"/> VK156 (SR) <input type="checkbox"/> VK2523 (SR OH) <input type="checkbox"/> VK178 (QR) <input type="checkbox"/> VK2773 (QR OH) <input type="checkbox"/> VK2883 (QR OH*) *Fusible Link 165° 205° 280° (Circle temp)	Vertical Sidewall <input type="checkbox"/> VK 157 (SR)* *Available in Chrome only	Finish <input type="checkbox"/> Chrome (F) <input type="checkbox"/> White (M) <input type="checkbox"/> White w/chrome escutcheon & sleeve (MF) <input type="checkbox"/> ENT (JN) Temperature <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) <input type="checkbox"/> 286°F (141°C) (G)	Recessed Flush	Pendent <input type="checkbox"/> VK482 (QR)	Finish <input type="checkbox"/> White Polyester (M-/W) Temperature <input type="checkbox"/> 165°F (74°C) (C) <input type="checkbox"/> 205 °F (96°C) (E)
	Lengths in ½" increments	Lengths in ¼" increments						

Recessed Adjustable	Pendent <input type="checkbox"/> VK158 (SR) <input type="checkbox"/> VK164 (SR LO) <input type="checkbox"/> VK186 (SR**) <input type="checkbox"/> VK169 (SR***) <input type="checkbox"/> VK180 (QR) <input type="checkbox"/> VK181 (QR LO) <input type="checkbox"/> VK186 (QR**) <input type="checkbox"/> VK290 (QR LO*) *Fusible Link 165° 205° **Ext. Coverage 155° 175° (Circle temp) ***Stainless Steel	ELO Pendent <input type="checkbox"/> VK545 (SR ELO)* <input type="checkbox"/> VK548 (QR ELO)* *Fusible Link 165° 205° 280° Brass Chrome White (Circle temp and finish) Lengths in 6" increments, 12"-28" Note: Insulating boot included.	Horizontal Sidewall <input type="checkbox"/> VK162 (SR) <input type="checkbox"/> VK2543 (SR OH) <input type="checkbox"/> VK188 (SR**) <input type="checkbox"/> VK182 (QR) <input type="checkbox"/> VK2793 (QR OH) <input type="checkbox"/> VK188 (QR**) <input type="checkbox"/> VK2923 (QR OH*) *Fusible Link 165° 205° **Ext. Coverage 155° 175° (Circle temp)	Vertical Sidewall <input type="checkbox"/> VK161 (SR)	Finish <input type="checkbox"/> Chrome (F) <input type="checkbox"/> White (M) <input type="checkbox"/> ENT (JN) Temperature <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) Lengths in ¼" increments	Concealed	Pendent <input type="checkbox"/> VK190 (SR) <input type="checkbox"/> VK192 (SR LO) <input type="checkbox"/> VK196 (SR**) <input type="checkbox"/> VK194 (QR) <input type="checkbox"/> VK196 (QR***) **SR Ext Cov 155° ***QR Ext Cov 135° 155° 175° (Circle temp)	Finish <input type="checkbox"/> Chrome (F) <input type="checkbox"/> White (M) <input type="checkbox"/> Ivory (M-/I) <input type="checkbox"/> Black (M-/B) Temperature Sprinklers <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) Covers <input type="checkbox"/> 135°F (57°C) (A) <input type="checkbox"/> 165°F (74°C) (C)
	Lengths in ¼" increments	Lengths in ¼" increments						

Plain Barrel	Pendent <input type="checkbox"/> VK150 (SR) <input type="checkbox"/> VK166 (SR LO) <input type="checkbox"/> VK168 (SR**) <input type="checkbox"/> VK172 (QR) <input type="checkbox"/> VK173 (QR LO) <input type="checkbox"/> VK282 (QR LO*) *Fusible Link 165° 205° 280° (Circle temp) **Stainless Steel	ELO Pendent <input type="checkbox"/> VK544 (SR ELO)* <input type="checkbox"/> VK547 (QR ELO)* *Fusible Link 165° 205° 280° Brass Chrome White (Circle temp and finish) Lengths in 6" increments, 12"-48" Note: Insulating boot included.	Horizontal Sidewall <input type="checkbox"/> VK152 (SR) <input type="checkbox"/> VK2503 (SR OH) <input type="checkbox"/> VK174 (QR) <input type="checkbox"/> VK2753 (QR OH) <input type="checkbox"/> VK2843 (QR OH*) *Fusible Link (165°, 205°, 280°) (Circle temp)	Vertical Sidewall <input type="checkbox"/> VK153 (SR)	Upright <input type="checkbox"/> VK160 (SR)* <input type="checkbox"/> VK184 (QR)* *Available in Brass only	Finish <input type="checkbox"/> Chrome (F) <input type="checkbox"/> Brass (A) <input type="checkbox"/> ENT (JN) Temperatures <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) <input type="checkbox"/> 286°F (141°C) (G) Lengths in ½" increments	A or B Dim: _____ _____ _____ _____ _____ _____ _____ _____	Qty: _____ _____ _____ _____ _____ _____ _____ _____
---------------------	---	---	--	---	--	---	--	---

All part numbers listed are NPT thread size.

