
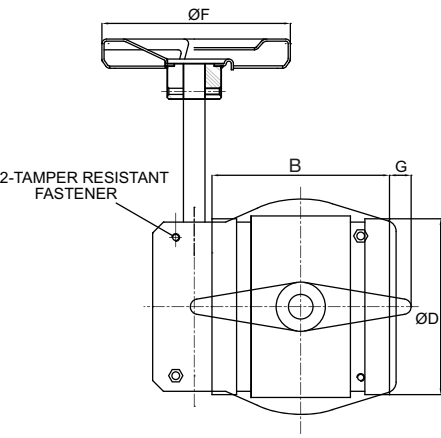


Butterfly Valve
Grooved End

- Size: 2 ½ through 8
- Working Pressure: 300psi (21.5 bars)
- Max. Test Pressure: 600psi (43.0 Bars)
- Working Temperature: 250F (120°C)
- Tampered Switch for Indoor and Outdoor use
- Meets MSS SP67 & AWWA C606
- Top Flange ISO 5211

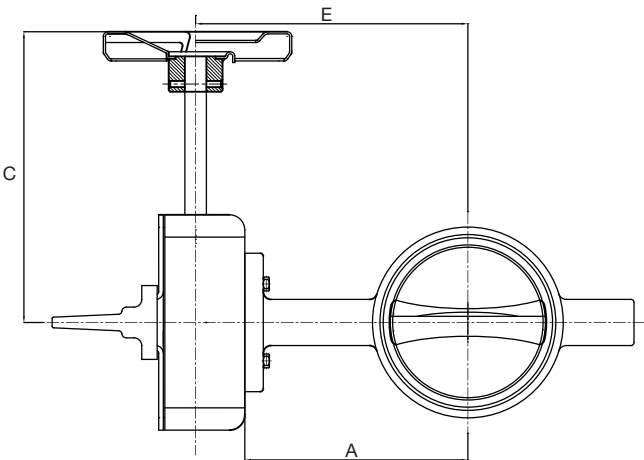

COMPONENTS	MATERIAL
Body	Ductile Iron, ASTM A536, Nylon-11 Coated
Disc	Ductile Iron ASTM B 148, EPDM Rubber Encapsulated
Stem	Stainless Steel, Hardened & Tempered
Housing	Ductile Iron (ASTM A-536)
Handwheel	Ductile Iron (ASTM A-536)

VALVE SIZE	ITEM CODE	DIMENSION (IN)						
		A	B	C	D	E	F	G
2 1/2"	UFP025SGB	4.48"	1.75"	4.24"	2.88"	5.50"	3.90"	4.13"
3"	UFP026SGB	4.73"	1.75"	4.24"	3.50"	5.76"	3.90"	4.13"
4"	UFP027SGB	5.73"	1.75"	4.24"	4.50"	6.75"	3.90"	4.13"
6"	UFP028SGB	7.07"	2.11"	5.79"	6.63"	8.45"	4.29"	4.88"
8"	UFP029	8.03"	5.80"	8.19"	8.62"	9.29"	8.86"	9.50"