



# Fire Extinguishers from Viking

## Rugged and Dependable Models by Strike First



### ABC Multi-Purpose Fire Extinguishers

ABC Seamless Steel Cylinder Dry Chemical with non-corrosive pull pin, completely rechargeable, anodized aluminum valve. Cylinder has high corrosion and impact resistant finish (red epoxy). Comes complete with wall bracket or vehicle bracket and a 6 year warranty.

ABC Multipurpose Models	Part No.	UL Rating	Skid Qty.
2.5 lb. with Vehicle Bracket	19464	1A:10BC	300
5 lb. with Wall Hook	19465	2A:10BC	200
5 lb. with Vehicle Bracket	19466	2A:10BC	200
5 lb. with Wall Hook	19467	3A:40BC	200
5 lb. with Vehicle Bracket	19468	3A:40BC	200
10 lb. with Wall Hook	19469	4A:80BC	120
20 lb. with Wall Hook	19470	10A:120BC	50
30 lb. with Wall Hook	19471	10A:120BC	25



### BC Standard Dry Chemical Fire Extinguishers

BC Seamless Steel Cylinder Dry Chemical with non-corrosive pull pin, completely rechargeable, anodized aluminum valve. Cylinder has high corrosion and impact resistant finish (red epoxy). Comes complete with wall bracket or vehicle bracket and a 6 year warranty.

BC Dry Chemical Models	Part No.	UL Rating
2.75 lb. with Vehicle Bracket	19474	10BC
5 lb. with Wall Hook	19475	10BC
5 lb. with Vehicle Bracket	19476	10BC
10 lb. with Wall Hook	19477	60BC
20 lb. with Wall Hook	19478	80BC

Trusted above all.™



# Fire Extinguishers from Viking

Rugged and Dependable Models by Strike First



## ABC Chrome Fire Extinguishers

ABC Seamless Steel Cylinder Dry Chemical—chrome plated.

ABC Chrome Models	Part No.	UL Rating
2.5 lb. with Vehicle Bracket	19472	1A:10BC
5 lb. with Wall Hook	19473	3A:40BC



## Kitchen Class and Water Fire Extinguishers

### Class K Kitchen Fire Extinguisher

Very effective for use on combustible vegetable or animal fats in commercial cooking equipment.

### Water Fire Extinguisher

Cooling, soaking and penetrating effect of a 40 ft. stream of water. The 40 second discharge time makes it very effective for inexperienced operators for use on Class A fires. Leaves no powder residue.

Kitchen Class Model	Part No.
6L Kitchen Class 1A:K with Wall Hook	19480

Pressurized Water Model	Part No.
9L Water 2A with Wall Hook	19479

### The Viking Corporation

210 N. Industrial Park Drive, Hastings, MI 49058

Telephone: (877) 384-5464  
www.vikinggroupinc.com

Trusted above all.™




## BC Carbon Dioxide Fire Extinguishers

CO2 Aluminum Cylinder Carbon Dioxide, with CO2 squeeze grip operation. Chrome plated valve is precision machined with stainless steel top and bottom handles. The finest CO2 valve manufactured in the world today. Aluminum cylinder — complete with wall bracket and a 6 year warranty.

BC Carbon Dioxide Models	Part No.	UL Rating
5 lb. with Wall Hook	19481	5BC
10 lb. with Wall Hook	19482	10BC
15 lb. with Wall Hook	19483	10BC
20 lb. with Wall Hook	19484	10BC

## Vehicle/U.S.C.G. Marine Brackets

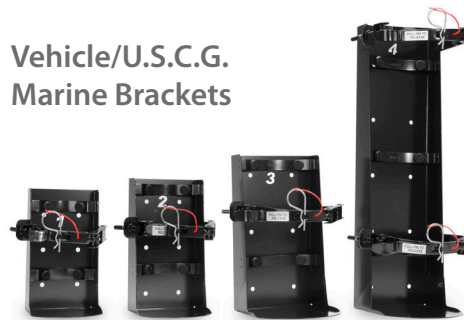

## Fire Extinguisher Cabinets

Cabinet Models	Part No.
5 lb. DC Galvanized (C-100)	19500
10 lb. DC Galvanized (C-199)	19501
20 lb. DC Galvanized (C-104)	19502

