


FIRE VALVES

- Size: 2 1/2 Through 8
- Working Pressure: 300 psi (21.5 Bars)
- Factory Installed UL Approved Tampered Switch for Indoor and Outdoor Use
- Trademark: Global Safety Products, Inc.
- Max. Test Pressure: 600 psi (43.0 Bars)
- Working Tempure: 250F (120°C)

DESCRIPTION

GROOVED END BUTTERFLY VALVE

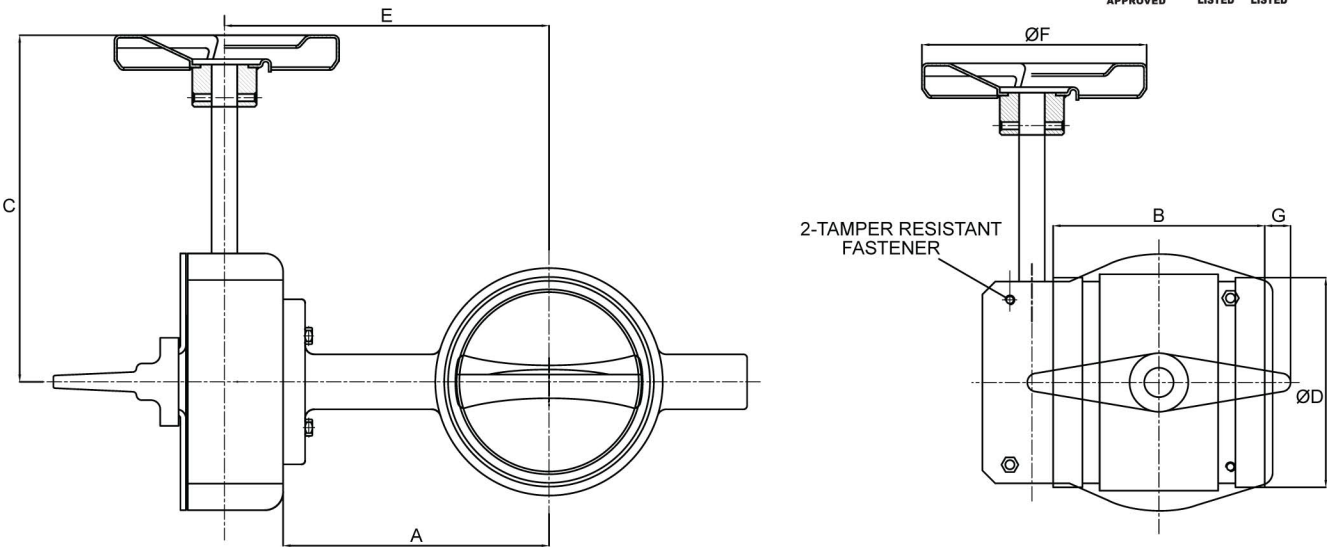

COMPONENT	MATERIAL
Body	Ductile Iron, EPDM Encapsulated
Disc	Al-Bronze, Ni-Cr Plated
Stem	Stainless Steel, Hardened & Tempered
Housing	Ductile Iron (ASTM A-536)
Hand Wheel	Ductile Iron (ASTM A-536)

VALVE SIZE	ITEM CODE	A	B	C	D	E	F	G
2 1/2"	UFP025	4.13"	3.80"	6.61"	2.88"	5.39"	4.92"	
3"	UFP026	4.41"	3.80"	6.61"	3.50"	5.67"	4.92"	
4"	UFP027	5.71"	4.54"	6.61"	4.50"	6.97"	4.92"	
6"	UFP028	7.05"	5.21"	8.19"	6.63"	8.31"	8.86"	0.27"
8"	UFP029	8.03"	5.80"	8.19"	8.62"	9.29"	8.86"	0.95"